


Non-return valves

Both sides fitted with UNF inner thread according to SAE J 514 and ISO 11926-1

Opening pressure 1 bar (standard design)

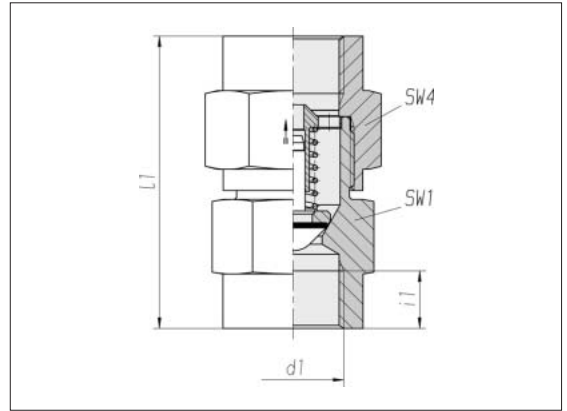

Series Tube OD	Pressure*	d1	SW1	SW4	l1	i1	kg/100 approx.	Order No.
S 6	PB 630	7/16-20 UNF	19	19	57.5	4	11.5	0 6 70 35 20 00
S 8	PB 630	1/ 2-20 UNF	19	19	57.5	5	10.1	0 6 70 36 20 00
S 10	PB 630	9/16-18 UNF	22	24	68	7	17.4	0 6 70 37 20 00
S 12	PB 630	3/ 4-16 UNF	27	27	74.5	8	25.6	0 6 70 38 20 00
S 16	PB 400	7/ 8-14 UNF	32	36	80	12	44.0	0 6 70 39 20 00
S 20	PB 400	1 1/16-12 UN	41	46	91.5	16	79.8	0 6 70 40 20 00
S 25	PB 400	1 5/16-12 UN	46	50	98	20	93.0	0 6 70 41 20 00
S 30	PB 250	1 5/ 8-12 UN	55	60	104	25	153.8	0 6 70 42 20 00
S 38	PB 250	1 7/ 8-12 UN	65	70	117	32	221.4	0 6 70 44 20 00

* Test pressure PP = 1.5 x table value