


Raccordi Femmina Sede JIC 37°

JIC Females 37° Cone

JIC 37° Dichtkegel


ISO 12151-5 (ISO 8434-2)

## DKJ 90

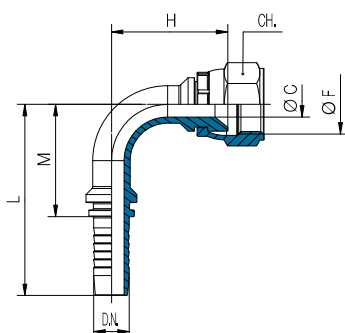

|   | <b>CODICE</b><br>Part n°<br>Bestell-Nr. | <b>Filetto</b><br>Thread<br>Gewinde | <b>Ø F</b><br>Ø F<br>Ø F | <b>DN Tubo</b><br>DN Hose<br>DN Schlauch | <b>CH</b> | <b>L</b> | <b>Ø C</b> | <b>H</b> | <b>M</b> |
|---|---|-------------------------------------|--------------------------|--|-----------|----------|------------|----------|----------|
| a | S 30 52 0 604 005 H                     | 7/16" - 20 UNF                      |                          | 3/16" 05                                 | 14        | 47,5     | 3          | 26       | 25,5     |
| a | S 30 52 0 604 006 H                     | 7/16" - 20 UNF                      |                          | 1/4" 06                                  | 14        | 57       | 4          | 26       | 29       |
| a | S 30 52 0 606 006 H                     | 1/2" - 20 UNF                       |                          | 1/4" 06                                  | 17        | 57       | 4          | 27       | 29       |
| a | S 30 52 0 608 006 A                     | 9/16" - 18 UNF                      |                          | 1/4" 06                                  | 19        | 57       | 4          | 28       | 29       |
| a | S 30 52 0 608 008 A                     | 9/16" - 18 UNF                      |                          | 5/16" 08                                 | 19        | 57,5     | 5,5        | 30,5     | 29,5     |
| a | S 30 52 0 608 010 A                     | 9/16" - 18 UNF                      |                          | 3/8" 10                                  | 19        | 63       | 7          | 35       | 33,5     |
| a | S 30 52 0 610 010 A                     | 3/4" - 16 UNF                       |                          | 3/8" 10                                  | 24        | 63       | 7          | 37       | 33,5     |
| a | S 30 52 0 610 013 A                     | 3/4" - 16 UNF                       |                          | 1/2" 12                                  | 24        | 71,5     | 9,5        | 42,5     | 42       |
| a | S 30 52 0 613 010 A                     | 7/8" - 14 UNF                       |                          | 3/8" 10                                  | 27        | 63       | 7          | 38       | 33,5     |
| a | S 30 52 0 613 013 A                     | 7/8" - 14 UNF                       |                          | 1/2" 12                                  | 27        | 71,5     | 9,5        | 43,5     | 42       |
| a | S 30 52 0 613 016 A                     | 7/8" - 14 UNF                       |                          | 5/8" 16                                  | 27        | 87       | 12,5       | 54       | 53       |
| a | S 30 52 0 619 013 A                     | 1 1/16" - 12 UN                     |                          | 1/2" 12                                  | 32        | 71,5     | 9,5        | 45       | 42       |
| a | S 30 52 0 619 016 A                     | 1 1/16" - 12 UN                     |                          | 5/8" 16                                  | 32        | 87       | 12,5       | 54,5     | 53       |
| a | S 30 52 0 619 019 A                     | 1 1/16" - 12 UN                     |                          | 3/4" 19                                  | 32        | 97       | 15         | 56       | 58       |
| a | S 30 52 0 622 019 A                     | 1 3/16" - 12 UN                     |                          | 3/4" 19                                  | 36        | 99       | 15         | 58,5     | 60       |
| a | S 30 52 0 625 019 A                     | 1 5/16" - 12 UN                     |                          | 3/4" 19                                  | 41        | 99       | 15         | 58,5     | 60       |
| a | S 30 52 0 625 025 A                     | 1 5/16" - 12 UN                     |                          | 1" 25                                    | 41        | 126      | 19,5       | 70,5     | 79       |
| a | S 30 52 0 632 025 A                     | 1 5/8" - 12 UN                      |                          | 1" 25                                    | 50        | 126      | 19,5       | 72,5     | 79       |
| a | S 30 52 0 632 032 A                     | 1 5/8" - 12 UN                      |                          | 1 1/4" 31                                | 50        | 150,5    | 26         | 86       | 96       |
| a | S 30 52 0 638 032 A                     | 1 7/8" - 12 UN                      |                          | 1 1/4" 31                                | 60        | 150,5    | 26         | 87       | 96       |
| a | S 30 52 0 638 038 A                     | 1 7/8" - 12 UN                      |                          | 1 1/2" 38                                | 60        | 175,5    | 32         | 100,5    | 117,5    |
| a | S 30 52 0 650 050 A                     | 2 1/2" - 12 UN                      |                          | 2" 51                                    | 75        | 216,5    | 42         | 135      | 144      |

## DKJ 45

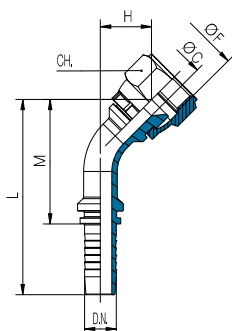

|   |                     |                 |  |           |    |       |      |      |       |
|---|---------------------|-----------------|--|-----------|----|-------|------|------|-------|
| a | S 30 82 0 604 006 A | 7/16" - 20 UNF  |  | 1/4" 06   | 14 | 61,5  | 4    | 12,5 | 33,5  |
| a | S 30 82 0 606 006 H | 1/2" - 20 UNF   |  | 1/4" 06   | 17 | 62    | 4    | 13,5 | 34    |
| a | S 30 82 0 608 006 A | 9/16" - 18 UNF  |  | 1/4" 06   | 19 | 62,5  | 4    | 14   | 34,5  |
| a | S 30 82 0 608 008 A | 9/16" - 18 UNF  |  | 5/16" 08  | 19 | 64    | 5,5  | 15   | 36    |
| a | S 30 82 0 608 010 A | 9/16" - 18 UNF  |  | 3/8" 10   | 19 | 70,5  | 7    | 17,5 | 41    |
| a | S 30 82 0 610 010 A | 3/4" - 16 UNF   |  | 3/8" 10   | 24 | 72    | 7    | 19   | 42,5  |
| a | S 30 82 0 610 013 A | 3/4" - 16 UNF   |  | 1/2" 12   | 24 | 80,5  | 9,5  | 20,5 | 51    |
| a | S 30 82 0 613 010 A | 7/8" - 14 UNF   |  | 3/8" 10   | 27 | 72,5  | 7    | 19,5 | 43    |
| a | S 30 82 0 613 013 A | 7/8" - 14 UNF   |  | 1/2" 12   | 27 | 81,5  | 9,5  | 21,5 | 52    |
| a | S 30 82 0 613 016 A | 7/8" - 14 UNF   |  | 5/8" 16   | 27 | 96,5  | 12,5 | 25,5 | 62,5  |
| a | S 30 82 0 619 013 A | 1 1/16" - 12 UN |  | 1/2" 12   | 32 | 82,5  | 9,5  | 22,5 | 53    |
| a | S 30 82 0 619 016 A | 1 1/16" - 12 UN |  | 5/8" 16   | 32 | 97    | 12,5 | 26   | 63    |
| a | S 30 82 0 619 019 A | 1 1/16" - 12 UN |  | 3/4" 19   | 32 | 108   | 15   | 28,5 | 69    |
| a | S 30 82 0 622 019 A | 1 3/16" - 12 UN |  | 3/4" 19   | 36 | 108,5 | 15   | 29   | 69,5  |
| a | S 30 82 0 625 019 A | 1 5/16" - 12 UN |  | 3/4" 19   | 41 | 108,5 | 15   | 29   | 69,5  |
| a | S 30 82 0 625 025 A | 1 5/16" - 12 UN |  | 1" 25     | 41 | 134,5 | 19,5 | 32,5 | 87,5  |
| a | S 30 82 0 632 025 A | 1 5/8" - 12 UN  |  | 1" 25     | 50 | 135,5 | 19,5 | 34   | 88,5  |
| a | S 30 82 0 632 032 A | 1 5/8" - 12 UN  |  | 1 1/4" 31 | 50 | 161   | 26   | 41   | 106,5 |
| a | S 30 82 0 638 032 A | 1 7/8" - 12 UN  |  | 1 1/4" 31 | 60 | 162   | 26   | 42   | 107,5 |
| a | S 30 82 0 638 038 A | 1 7/8" - 12 UN  |  | 1 1/2" 38 | 60 | 184,5 | 32   | 46,5 | 126,5 |
| a | S 30 82 0 650 050 A | 2 1/2" - 12 UN  |  | 2" 51     | 75 | 231   | 42   | 67   | 158,5 |

a: dado pressato

a: crimped nut

a: verkrimpte Überwurfmutter

Articoli di basso consumo su richiesta

Slow moving articles available on request

Artikel mit geringen Stückzahlen auf Anfrage