


Ghiere a pressare
 Swaged Ferrules
 Pressfassungen

NO SKIVE

PF 22

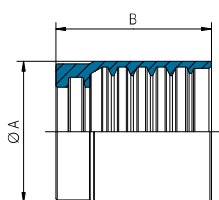


Ghiere per tubo SAE 100 R1AT-R2AT EN 853 1SN-2SN EN 857 2SC

Swaged ferrule for SAE 100 R1AT-R2AT EN 853 1SN-2SN EN 857 2SC hose
 Pressfassung für SAE 100 R1AT-R2AT EN 853 1SN-2SN EN 857 2SC Schlauch

CODICE Part n° Bestell-Nr.	DN Tubo DN Hose DN Schlauch	Ø A	B
S 30 00 245 000 005	3/16" 5	21	23,5
S 30 00 245 000 006	1/4" 6	23	30
S 30 00 245 000 008	5/16" 8	24	30
S 30 00 245 000 010	3/8" 10	26	31
S 30 00 245 000 013	1/2" 12	29	32
S 30 00 245 000 016	5/8" 16	33	36
S 30 00 245 000 019	3/4" 19	37	42,5
S 30 00 245 000 025	1" 25	46	51
S 30 00 245 000 032	1 1/4" 31	59	57,5
S 30 00 245 000 038	1 1/2" 38	67	60,5
S 30 00 245 000 050	2" 51	80	74

PF 23

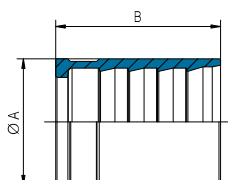

Ghiere per tubo Termoplastico SAE 100 R7 R8 EN 855 R7 R8 1 Treccia acciaio e EN 857 1SC

Crimp ferrule for Thermoplastic SAE 100 R7 R8 EN 855 R7 R8 1 steel Braid and EN 857 1SC
 Pressfassung für Thermoplastschlauch SAE 100 R7 R8 EN 855 R7 R8 1 Standarddrahtgeflecht und EN 857 1SC

CODICE Part n° Bestell-Nr.	DN Tubo DN Hose DN Schlauch	Ø A	B
S 30 00 150 000 005	3/16" 5	14	26,5
S 30 00 150 000 006	1/4" 6	18	30,5
S 30 00 150 000 008	5/16" 8	19	32
S 30 00 150 000 010	3/8" 10	22	33
S 30 00 150 000 013	1/2" 12	26	34
S 30 00 150 000 016			
S 30 00 150 000 019			
S 30 00 150 000 025			