


24/37° support sleeves

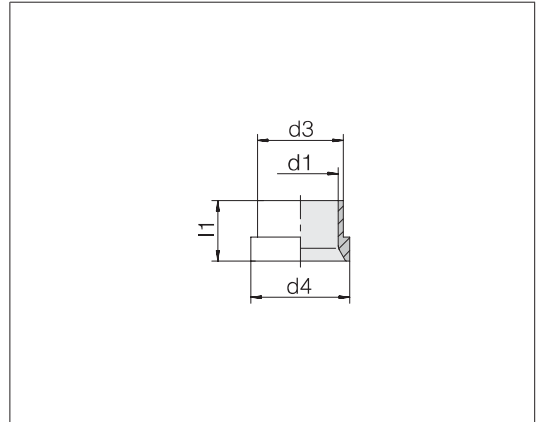

3

| Series Tube OD d1 | Pressure | d3 | d4 | l1 | kg/100 ca. | Order-No. | Designation |
|-------------------------|------------|------|------|------|---------------|------------|-----------------|
| L/S 6 | PN 500/630 | 7.6 | 10.2 | 10.5 | 0.2 | 0041202000 | 24-24/37R-L/S6 |
| L/S 8 | PN 500/630 | 9.3 | 12.2 | 11 | 0.3 | 0041212000 | 24-24/37R-L/S8 |
| L/S 10 | PN 500/630 | 11.5 | 14.2 | 12.5 | 0.4 | 0041222000 | 24-24/37R-L/S10 |
| L/S 12 | PN 400/630 | 13.6 | 16.2 | 13 | 0.5 | 0041232000 | 24-24/37R-L/S12 |
| L 15 | PN 400 | 17.5 | 20.2 | 14 | 1.0 | 0041242000 | 24-24/37R-L15 |
| L 18 | PN 400 | 21 | 24.2 | 14.5 | 1.5 | 0041252000 | 24-24/37R-L18 |
| L 22 | PN 250 | 24.2 | 27.8 | 18 | 1.7 | 0041262000 | 24-24/37R-L22 |
| L 28 | PN 250 | 30.2 | 33.8 | 17 | 2.0 | 0041272000 | 24-24/37R-L28 |
| L 35 | PN 250 | 38 | 42.7 | 19 | 3.8 | 0041282000 | 24-24/37R-L35 |
| L 42 | PN 250 | 45 | 49.7 | 21 | 5.2 | 0041292000 | 24-24/37R-L42 |
| S 14 | PN 630 | 17.5 | 20.2 | 14.5 | 1.2 | 0041302000 | 24-24/37R-S14 |
| S 16 | PN 630 | 18.5 | 22 | 17 | 1.3 | 0041312000 | 24-24/37R-S16 |
| S 20 | PN 400 | 24.2 | 27.8 | 17.5 | 2.5 | 0041322000 | 24-24/37R-S20 |
| S 25 | PN 400 | 28.5 | 32.8 | 20 | 3.2 | 0041332000 | 24-24/37R-S25 |
| S 30 | PN 400 | 34 | 39 | 21.5 | 4.9 | 0041342000 | 24-24/37R-S30 |
| S 38 | PN 400 | 42 | 48.5 | 26.5 | 7.7 | 0041352000 | 24-24/37R-S38 |