


## Anelli di tenuta per raccordi a flangia

Il materiale standard degli O-Ring è NBR

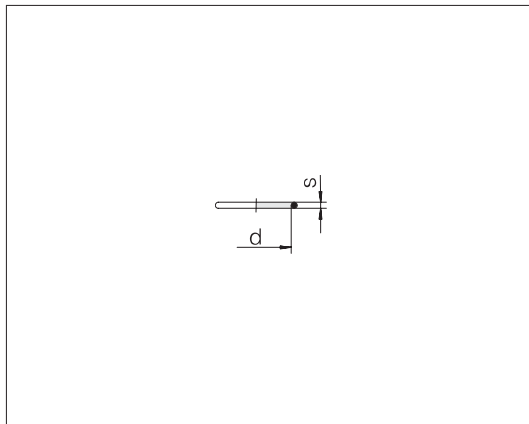

| Serie D est. tubo | Diametro circonferenza foro | Dim. fl. | d x s        | N. d'ordine | Denominazione          |
|-------------------|-----------------------------|----------|--------------|-------------|------------------------|
| L 10              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| L 12              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| L 15              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| L 15              | 40                          |          | 26 x 2,5     | 0900189990  | GP-OR-26x2,5-NBR90     |
| L 18              | 40                          |          | 26 x 2,5     | 0900189990  | GP-OR-26x2,5-NBR90     |
| L 18              |                             | 3/4      | 24,99 x 3,53 | 0906719990  | GP-OR-24,99x3,53-NBR90 |
| L 22              | 40                          |          | 26 x 2,5     | 0900189990  | GP-OR-26x2,5-NBR90     |
| L 22              |                             | 3/4      | 24,99 x 3,53 | 0906719990  | GP-OR-24,99x3,53-NBR90 |
| L 28              |                             | 1        | 32,92 x 3,53 | 0906729990  | GP-OR-32,92x3,53-NBR90 |
| L 28              | 40                          |          | 26 x 2,5     | 0900189990  | GP-OR-26x2,5-NBR90     |
| L 28              | 55                          |          | 32 x 2,5     | 0900929990  | GP-OR-32x2,5-NBR90     |
| L 35              |                             | 1 1/4    | 37,69 x 3,53 | 0906739990  | GP-OR-37,69x3,53-NBR90 |
| L 35              | 55                          |          | 32 x 2,5     | 0900929990  | GP-OR-32x2,5-NBR90     |
| L 42              |                             | 1 1/2    | 47,22 x 3,53 | 0906549990  | GP-OR-47,22x3,53-NBR90 |
| S 12              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| S 16              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| S 16              |                             | 1/2      | 18,64 x 3,53 | 0906749990  | GP-OR-18,64x3,53-NBR90 |
| S 16              |                             | 3/4      | 24,99 x 3,53 | 0906719990  | GP-OR-24,99x3,53-NBR90 |
| S 20              |                             | 3/4      | 24,99 x 3,53 | 0906719990  | GP-OR-24,99x3,53-NBR90 |
| S 20              | 35                          |          | 20 x 2,5     | 0906599990  | GP-OR-20x2,5-NBR90     |
| S 20              | 40                          |          | 26 x 2,5     | 0900189990  | GP-OR-26x2,5-NBR90     |
| S 20              | 55                          |          | 32 x 2,5     | 0900929990  | GP-OR-32x2,5-NBR90     |
| S 25              |                             | 1 1/4    | 37,69 x 3,53 | 0906739990  | GP-OR-37,69x3,53-NBR90 |
| S 25              | 55                          |          | 32 x 2,5     | 0900929990  | GP-OR-32x2,5-NBR90     |
| S 25              |                             | 3/4      | 24,99 x 3,53 | 0906719990  | GP-OR-24,99x3,53-NBR90 |
| S 30              | 55                          |          | 32 x 2,5     | 0900929990  | GP-OR-32x2,5-NBR90     |
| S 30              |                             | 1        | 32,92 x 3,53 | 0906729990  | GP-OR-32,92x3,53-NBR90 |
| S 30              |                             | 1 1/4    | 37,69 x 3,53 | 0906739990  | GP-OR-37,69x3,53-NBR90 |
| S 38              |                             | 1 1/2    | 47,22 x 3,53 | 0906549990  | GP-OR-47,22x3,53-NBR90 |
| S 38              |                             | 1 1/4    | 37,69 x 3,53 | 0906739990  | GP-OR-37,69x3,53-NBR90 |